


Ventuza burduf VASB-15-1/8-NBR-CT

Cod: 183515

FESTO

cu inel de etansare OL.

Tip iesit din fabricatie. Livrabil pana in 2010.

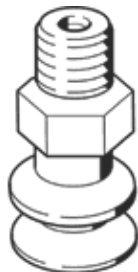

Fisa tehnica

Caracteristica	valoare
deschidere nominala	3 mm
diametru ventuza	15 mm
diametru efectiv ventuza	12 mm
structura constructiva	racord de vacuum deschis rotund, burduf incretit de 1,5 ori
mediu de operare	aer atmosferic
temperatura mediului	-20 ... 80 °C
forta de rupere la 70% vacuum	7,9 N
filet de fixare	G1/8
fixarea ventuzei	G 1/8
racord de vacuum	G1/8
duritate Shore	73
indicatie material	Fara cupru si PTFE
informatii referitoare la material pentru ventuza	TPE-U(PU)