


Gripper cu ventuza ESG-6

Cod: 189169

FESTO

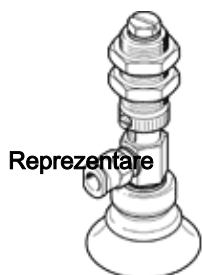

Fisa tehnica

Fisa date generala - valorile individuale depind de configuratia Dvs.

Caracteristica	valoare
Diametru ventuza	6 mm
pozitie instalare	vertical
Caracteristici speciale	Antistatic
Structura constructiva	racord de vacuum sus racord de vacuum lateral cu compensare a inaltimii cu compensator lung de inaltime
Atribuire suport de ventuza	marimea 2
Forma ventuza	rotund plat
mediu de operare	Aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - Rezistenta redusa la coroziune
Temperatura mediului	-30 ... 200 °C
Racord de vacuum	M5 M10x1 QS-6 PK-4
Indicatie material	conform RoHS
Materialul ventuzei	BR FPM NBR PUR VMQ (silicon)