


Ventuza vacuum fara conector ESV-150-SS

Numar piesa: 191013

FESTO

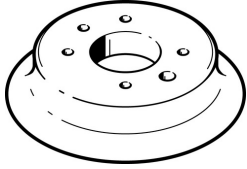

Fisa de date

Caracteristica	Valoare
Raza min. a piesei de prelucrat	480 mm
Diametrul ventuzei	150 mm
Volum de aspiratie	173.826 cm ³
Pozitie de conectare	sus
Pozitie de instalare	orice
Forma de ventuza	rotund plat
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 000032...0 000032
Presiunea nominala de functionare	-70 kPa -0.7 bar -10.15 000032
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364 zona III
Siguranta alimentara	vedeti informatii detaliate despre material
Temperatura ambianta	-30 °C...180 °C
Fora de mentinere la presiune de lucru nominala	900 N
Greutate produs	361 g
Culoare	transparent
Duritate Shore	50 +/- 5
Nota privind materialele	Conform RoHS
Material ventuze	VMQ (silicon)