


Ventuză vacuum fara conector ESV-200-SN

Numar piesa: 191015

FESTO

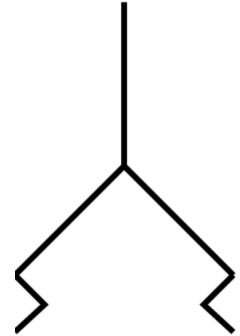

Fisa de date

Caracteristica	Valoare
Raza min. a piesei de prelucrat	680 mm
Diametrul ventuzei	200 mm
Volum de aspiratie	245.454 cm ³
Pozitie de conectare	sus
Pozitie de instalare	orice
Forma de ventuza	rotund plat
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 000032...0 000032
Presiunea nominala de functionare	-70 kPa -0.7 bar -10.15 000032
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364-A1-L
Siguranta alimentara	vedeti informatii detaliate despre material
Temperatura ambienta	-10 °C...70 °C
Forța de mentinere la presiune de lucru nominala	1610 N
Greutate produs	840 g
Culoare	negru
Duritate Shore	50 +/- 5
Nota privind materialele	Conform RoHS
Material ventuze	NBR