


Ventuza vacuum fara conector ESV-30-BS

Numar piesa: 191059

FESTO

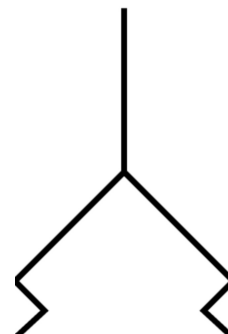

Fisa de date

| Caracteristica | Valoare |
|---|---|
| Ventuza de compensare a inaltimii | 8 mm |
| Raza min. a piesei de prelucrat | 80 mm |
| Diametrul ventuzei | 30 mm |
| Volum de aspiratie | 4.07 cm ³ |
| Pozitie de conectare | sus |
| Pozitie de instalare | orice |
| Forma de ventuza | burduf rotund de 1,5 ori |
| Presiune de lucru | -95 kPa...0 kPa -0.95 bar...0 bar -13.775 000032...0 000032 |
| Presiunea nominala de functionare | -70 kPa -0.7 bar -10.15 000032 |
| Mediu de operare | aer atmosferic conform ISO 8573-1:2010 [7::-] |
| Conformitatea LABS | VDMA24364 zona III |
| Siguranta alimentara | vedeti informatii detaliate despre material |
| Temperatura ambianta | -30 °C...180 °C |
| Fora de mentinere la presiune de lucru nominala | 26.2 N |
| Greutate produs | 3.6 g |
| Culoare | transparent |
| Duritate Shore | 50 +/- 5 |
| Nota privind materialele | Conform RoHS |
| Material ventuze | VMQ (silicon) |