


Ventuza vacuum fara conector ESV-40-BU

Numar piesa: 191061

FESTO

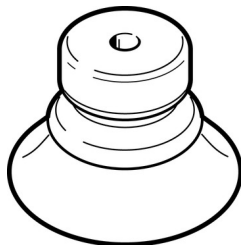

Fisa de date

Caracteristica	Valoare
Ventuza de compensare a inaltimii	9.5 mm
Raza min. a piesei de prelucrat	90 mm
Diametrul ventuzei	40 mm
Volum de aspiratie	11.699 cm ³
Pozitie de conectare	sus
Pozitie de instalare	orice
Forma de ventuza	burduf rotund de 1,5 ori
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 000032...0 000032
Presiunea nominala de functionare	-70 kPa -0.7 bar -10.15 000032
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364 zona III
Siguranta alimentara	vedeti informatii detaliate despre material
Temperatura ambianta	-20 °C...60 °C
Fora de mentinere la presiune de lucru nominala	52.3 N
Greutate produs	9.8 g
Culoare	albastru
Duritate Shore	60 +/- 5
Nota privind materialele	Conform RoHS
Material ventuze	PUR