


# Ventuza vacuum fara conector ESV-80-BU

Numar piesa: 191067

FESTO

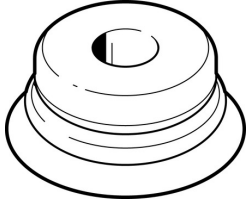

## Fisa de date

Caracteristica	Valoare
Ventuza de compensare a inaltimii	10 mm
Raza min. a piesei de prelucrat	430 mm
Diametrul ventuzei	80 mm
Volum de aspiratie	63.9 cm <sup>3</sup>
Pozitie de conectare	sus
Pozitie de instalare	orice
Forma de ventuza	burduf rotund de 1,5 ori
Presiune de lucru	-95 kPa...0 kPa -0.95 bar...0 bar -13.775 000032...0 000032
Presiunea nominala de functionare	-70 kPa -0.7 bar -10.15 000032
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7::-]
Conformitatea LABS	VDMA24364 zona III
Siguranta alimentara	vedeti informatii detaliate despre material
Temperatura ambianta	-20 °C...60 °C
Fora de mentinere la presiune de lucru nominala	213.6 N
Greutate produs	39 g
Culoare	albastru
Duritate Shore	60 +/- 5
Nota privind materialele	Conform RoHS
Material ventuze	PUR