


Filtru vacuum ESF-4A

Numar piesa: 191203

FESTO

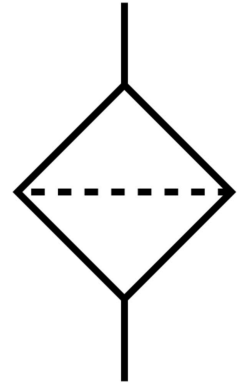

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Finete de filtrare	10 μm
Presiune de lucru	-0.95 bar...4 bar
Debit la presiune negativa = -0,075 MPa (-0,75 bari, -10,875 psi)	260 l/min
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-A1-L
Temperatura ambianta	0 °C...60 °C
Greutate produs	19 g
Tipul de montare	cu filet exterior prin racordul de vid
Conexiune pneumatica	M6
Racord de vacuum	M6
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material filtru	PVF
Material carcasa	Aluminiu Alama, nichelata