


## Set axial EAMM-A-D50-87A

Numar piesa: 2733781

FESTO

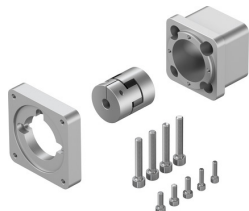

### Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	12 Nm
Greutate produs	860 g
Cod de interfata actuator	D50B
Codul interfetei motor In	87A
Nota privind materialele	Conform RoHS