


# Unitate ghidare FENG-32-160-KF

Numar piesa: 34495

FESTO

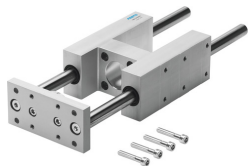

## Fisa de date

Caracteristica	Valoare
Dimensiune	32
Cursa	160 mm
Pozitie de instalare	orice
Ghidaj	Ghidaj cu bile de recirculare
Structura constructiva	Ghidaj
Protectie la explozie	Zona 1 (ATEX) Zona 2 (ATEX) Zona 21 (ATEX) Zona 22 (ATEX)
Conformitatea LABS	VDMA24364-B2-L
Temperatura ambianta	-20 °C...80 °C
Forta max. Fy	750 N
Forta max. Fy statica	1020 N
Forta max. Fz	750 N
Forta max. Fz statica	1020 N
Moment max. Mx	28 Nm
Moment max. Mx static	38 Nm
Max. Moment My	34 Nm
Moment My static max.	46 Nm
Moment max. Mz	34 Nm
Moment Mz static max.	46 Nm
Forta de deplasare	15 N
Greutate produs	1818 g
Tipul de montare	cu filet interior
Nota privind materialele	Conform RoHS
Material element de ghidare	Otel calit
Material carcasa	Aliaj de aluminiu forjat, anodizat
Material placa de jug	Aliaj de aluminiu forjat, anodizat