
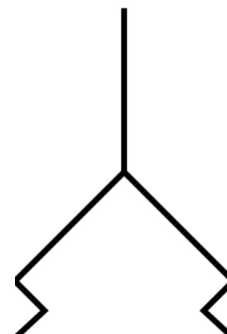


Ventuza vacuum VASB-100-1/4-NBR

Numar piesa: 35416

FESTO

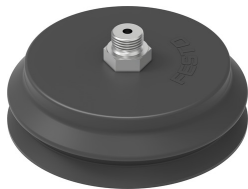

Fisa de date

Caracteristica	Valoare
Latimea nominala	4 mm
Diametrul ventuzei	100 mm
Diametru de aspiratie eficient	85 mm
Pozitie de conectare	sus
Forma de ventuza	burduf rotund de 1,5 ori
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-20 °C...80 °C
Fora de smulgere la 70 % vacuum	397 N
Fora de mentinere la presiune de lucru nominala	397 N
Filet de fixare	G1/4
Fixarea ventuzei	G 1/4
Racord de vacuum	G1/4
Culoare	negru
Duritate Shore	60 +/- 5
Material pivot de insurubare	Zinc turnat sub presiune
Nota privind materialele	Conform RoHS
Material ventuze	NBR