


Ventuza VAS-8-M5-PUR

Cod: 36135

FESTO

cu inel de etansare OL.

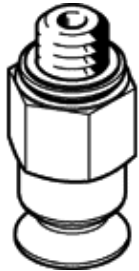

Fisa tehnica

Caracteristica	valoare
deschidere nominala	2 mm
diametru ventuza	8 mm
diametru efectiv ventuza	5,5 mm
structura constructiva	racord de vacuum deschis rotund, standard
mediu de operare	aer atmosferic
temperatura mediului	-20 ... 60 °C
forta de rupere la 70% vacuum	1,6 N
filet de fixare	M5
fixarea ventuzei	M5
racord de vacuum	M5
duritate Shore	62
informatii referitoare la material pentru fus cu insurubare	alama
informatii referitoare la material pentru ventuza	TPE-U(PU)