


Ventuza VAS-40-1/4-PUR

Cod: 36138

FESTO

cu inel de etansare OL.

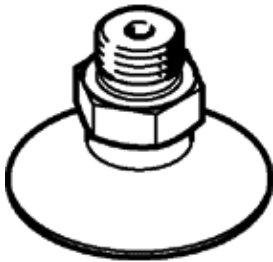

Fisa tehnica

Caracteristica	valoare
deschidere nominala	4 mm
diametru ventuza	40 mm
diametru efectiv ventuza	32 mm
structura constructiva	racord de vacuum deschis rotund, standard
mediu de operare	aer atmosferic
temperatura mediului	-20 ... 60 °C
forta de rupere la 70% vacuum	56 N
filet de fixare	G1/4
fixarea ventuzei	G 1/4
racord de vacuum	G1/4
duritate Shore	62
informatii referitoare la material pentru fus cu insurubare	zinc turnat sub presiune
informatii referitoare la material pentru ventuza	TPE-U(PU)