 



Ventil pneumatic JD-5-PK-3

Numar piesa: 4901

FESTO

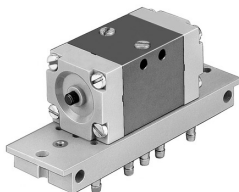

Fisa de date

| Caracteristica | Valoare |
|--------------------------------------|--|
| Funcție de ventil | 5/2 bistabil-dominant |
| Debit nominal normal | 105 l/min |
| Racord pneumatic de lucru | PK-3 |
| Presiune de lucru | 1 bar...8 bar |
| Structura constructiva | Scaun-farfurie |
| Latimea nominala | 2.5 mm |
| Timp de comutare | 9 ms |
| Timp de comutare la (dominant) | 25 ms |
| Mediu de operare | Aer comprimat conform ISO 8573-1:2010 [7:-:-] |
| Conformitatea LABS | VDMA24364-B1/B2-L |
| Temperatura ambianta | 0 °C...60 °C |
| Greutate produs | 130 g |
| Tipul de montare | optional: pe placa de racordare pe cadrul de montare cu orificiu de trecere |
| Conector aer auxiliar de control 12 | PK-3 |
| Conexiune aer auxiliar de control 14 | PK-3 |
| Conector pneumatic 1 | PK-3 |
| Conexiune pneumatica 2 | PK-3 |
| Conector pneumatic 3 | PK-3 |
| Conexiune pneumatica 4 | PK-3 |
| Conexiune pneumatica 5 | PK-3 |
| Nota privind materialele | Conform RoHS |
| Materialul placii de racordare | Alama Ranforsat cu PPS |
| Material garnituri | NBR |
| Material carcasa | Material plastic Zinc turnat sub presiune |