


# Ventuza vacuum fara conector ESV-80-GT

Numar piesa: 526004

FESTO

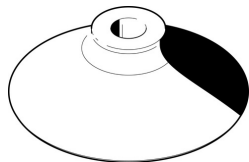

## Fisa de date

Caracteristica	Valoare
Compensarea inaltimii suport de ventuza	7.5 mm
Raza min. a piesei de prelucrat	100 mm
Diametrul ventuzei	80 mm
Volum de aspiratie	28.6 cm <sup>3</sup>
Pozitie de instalare	orice
Structura constructiva	rotund, in forma de clopot
Forma de ventuza	rotund adanc
Presiune de lucru	-0.95 bar...0 bar
Presiunea nominala de functionare	-0.7 bar
Mediu de operare	aer atmosferic conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364-A1-L
Temperatura ambianta	-10 °C...80 °C
Fora de smulgere la 70 % vacuum	245 N
Fora de mentinere la presiune de lucru nominala	245 N
Fora transversala la presiunea de lucru nominala	99 N
Greutate produs	30.9 g
Tipul de montare	prin racordul de vid
Culoare	rosu maro
Duritate Shore	72 +/- 5
Nota privind materialele	Conform RoHS
Material ventuze	Vulkollan