 



Modul de ramificare MS4-FRM-1/8-I

Cod: 536965

FESTO

cu functiune supapa integrata, directie debitului de tranzit de la stanga la dreapta.

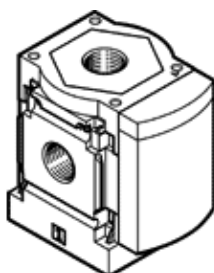

Fisa tehnica

Caracteristica	valoare
pozitie instalare	oricare
structura constructiva	modul de ramificatie cu supapa de sens unic
presiune de operare	0 ... 10 bar
debit standard in directia principala de curgere 1->2	1.200 l/min
debit standard la iesirea superioara	500 l/min
debit standard la iesirea inferioara	500 l/min
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:4:4] Inert gases
Note on operating and pilot medium	Lubricated operation possible (subsequently required for further operation)
clasa de rezistenta la coroziune KBK	2
temperatura de depozitare	-10 ... 60 °C
temperatura mediului	-10 ... 60 °C
greutate produs	160 g
racord pneumatic 1	G1/8
racord pneumatic 2	G1/8
racord pneumatic 3	G1/4
racord pneumatic 4	G1/4
indicatie material	Free of copper and PTFE conform RoHS
informatii referitoare la material pentru carcasa	aluminu turnat sub presiune