


# Set axial EAMM-A-D60-87A

Numar piesa: 543162

FESTO

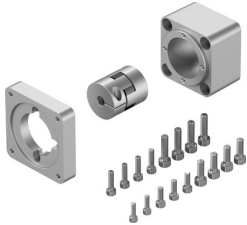

## Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	17 Nm
Greutate produs	890 g
Cod de interfata actuator	D60A D60B D60C
Codul interfetei motor In	87A
Nota privind materialele	Conform RoHS