


Ventil siguranta vacuum ISV-M4

Numar piesa: 545996

FESTO

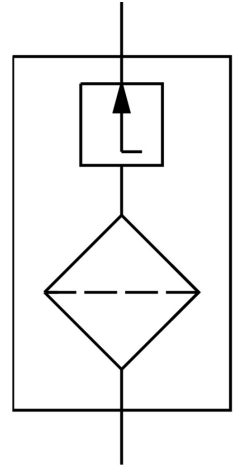

Fisa de date

| Caracteristica | Valoare |
|--|--|
| Dimensiune | M4 |
| Capacitate de impuls de cadere | 0.8 MPa 8 bar |
| Pozitie de instalare | orice |
| Presiune de lucru | -95 kPa...0 kPa -0.95 bar...0 bar |
| Debit volumetric de aspiratie necesar, la -0,05 MPa (-0,5 bari, -7,25 psi) | 1 l/min |
| Mediu de operare | Aer comprimat conform ISO 8573-1:2010 [7::-] |
| Clasa de rezistenta la coroziune KBK | 2 - Solicitare moderata din cauza coroziunii |
| Conformitatea LABS | VDMA24364-B1/B2-L |
| Temperatura ambianta | -10 °C...60 °C |
| Greutate produs | 1.5 g |
| Tipul de montare | insurubabil |
| Conector pneumatic 1 | M4 |
| Conexiune pneumatica 2 | M4 |
| Material filtru | Bronz sinterizat |
| Material carcasa | Aliaj de aluminiu forjat |