


## Filtru vacuum VAF-DB-1/4

Numar piesa: 547261

FESTO

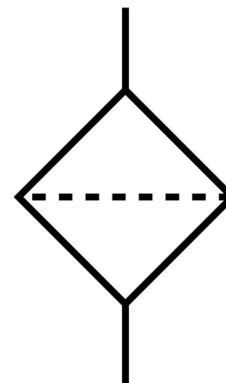

## Fisa de date

Caracteristica	Valoare
Pozitie de instalare	vertical
Finete de filtrare	80 µm
Presiune de lucru	-0.95 bar...0 bar
Indicatie referitoare la presiunea de lucru	Aplicare doar in sisteme cu vacuum deschise
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:-:-]
Conformitatea LABS	VDMA24364 zona III
Temperatura ambianta	-5 °C...50 °C
Cuplu de strangere max.	8.7 Nm
Greutate produs	71 g
Tipul de montare	Instalarea liniei cu suport de perete/suprafata
Conexiune pneumatica	G1/4
Racord de vacuum	G1/4
Nota privind materialele	Conform RoHS
Material garnituri	NBR
Material filtru	PE
Material carcasa	ranforsat PP PA
Capacitate de impuls de cadere	7 bar