


Aparatoare CPX-M-AK-M

Numar piesa: 548754

FESTO

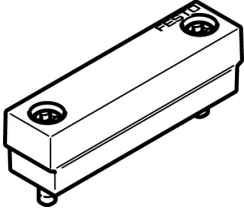

Fisa de date

| Caracteristica | Valoare |
|--------------------------------------|---|
| Latime | 11,5 mm |
| Inaltime | 13 mm |
| Lungime | 49 mm |
| Greutate produs | 15 g |
| Tip de protectie | IP65 IP67 in stare asamblata conform IEC 60529 |
| Temperatura ambianta | -5 °C...50 °C |
| Conformitatea LABS | VDMA24364-B2-L |
| Nota privind materialele | Conform RoHS |
| Clasa de rezistenta la coroziune KBK | 0 - nu este afectat de coroziune |
| Material suruburi | Otel galvanizat |
| Material garnituri | NBR |
| Material capac | Aluminiu turnat sub presiune |
| Umiditate relativa | 5 - 90 % fara condensare |