


Carcasa cuplaj EAMK-A-D40-44A/C

Numar piesa: 552157

FESTO

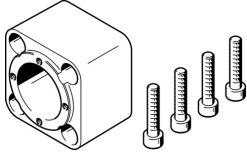

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Temperatura ambianta	-10 °C...60 °C
Greutate produs	216 g
Cod de interfata actuator	D40A D40B D40C
Cod de interfata carcasa de cuplare	44A 44C
Nota privind materialele	Conform RoHS