


Bara de racordare VABM-C7-12P-G18-5

Numar piesa: 552655

FESTO

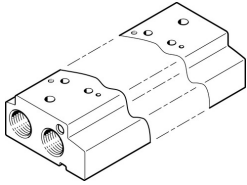

Fisa de date

| Caracteristica | Valoare |
|--------------------------------------|--|
| Numarul max. de pozitii de ventil | 5 |
| Clasa de rezistenta la coroziune KBK | 2 - Solicitare moderata din cauza coroziunii |
| Conformitatea LABS | VDMA24364-B2-L |
| Greutate produs | 147 g |
| Conector pneumatic 1 | G1/8 |
| Conector pneumatic 3 | G1/8 |
| Nota privind materialele | Conform RoHS |
| Material bara de racordare | Aliaj de aluminiu forjat |