


Set axial EAMM-A-P6-38A-42A

Numar piesa: 562644

FESTO

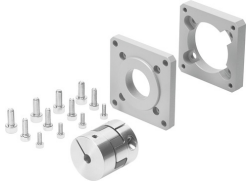

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	3.5 Nm
Greutate produs	160 g
Cod de interfata actuator	P6-38A
Codul interfetei motor In	42A
Cod de interfata carcasa de cuplare	38A.2
Nota privind materialele	Conform RoHS