
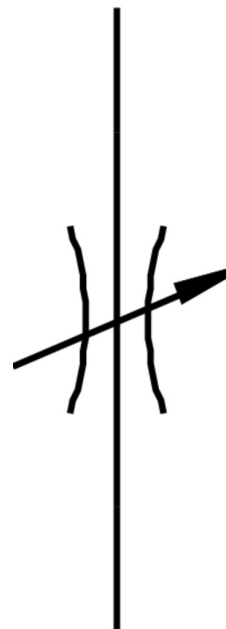


# Placa drosel VABF-S7-F1B5P1-F

Numar piesa: 563401

FESTO

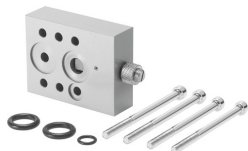

## Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Alimentarea cu aer pilot	extern intern
Presiune de lucru	0 MPa...1.2 MPa 0 bar...12 bar
Protectie la explozie	Zona 1 (ATEX) Zona 2 (ATEX) Zona 21 (ATEX) Zona 22 (ATEX)
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [7:-:-]
Clasa de rezistenta la coroziune KBK	4 - Mediu coroziv deosebit de puternic
Conformitatea LABS	VDMA24364 zona III
Tip de protectie	IP65
Tipul de montare	cu orificiu de trecere
Conexiune aer de control 12	G1/4
Conector pneumatic 1	G1/4
Conexiune pneumatica 2	Flansa 1/4 Schema de conectare NAMUR
Conector pneumatic 3	G1/4
Nota privind materialele	Conform RoHS

<b>Caracteristica</b>	<b>Valoare</b>
Materialul placii de racordare	Aluminiu ematalizat
Material garnituri	NBR