


# Racord rapid QS-F-G3/8-14H

Cod: 570437

FESTO

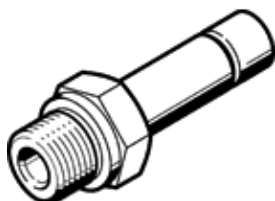

## Fisa tehnica

Caracteristica	valoare
marime de fabricatie	standard
deschidere nominala	12 mm
tip de etansare la fusul cu insurubare	inel de etansare
structura constructiva	principiu Push-Pull
Operating pressure complete temperature range	-0,95 ... 16 bar
mediu de operare	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
clasa de rezistenta la coroziune KBK	3
Food safety	to manufacturer's declaration
temperatura mediului	0 ... 150 °C
aprobare	Germanischer Lloyd
cuplul maxim de pornire	25 Nm
greutate produs	24 g
racord pneumatic 1	G3/8
racord pneumatic 2	For tubing outside diameter 14 mm
indicatie material	conform RoHS
informatii referitoare la material pentru carcasa	alama cromat si nichelat
informatii referitoare la material pentru etansare filet	FPM