


# Bloc racordare CPX-AB-1-7/8-DN

Numar piesa: 571052

FESTO

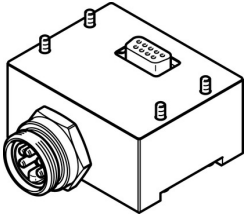

## Fisa de date

Caracteristica	Valoare
Dimensiuni l x L x H	65,5 mm x 30,5 mm x 62 mm
Tipul de montare	cu orificiu de trecere
Greutate produs	205 g
Temperatura ambianta	-5 °C...50 °C
Temperatura de depozitare	-20 °C...70 °C
Tip de protectie	IP65 IP67
Clasa de rezistenta la coroziune KBK	2 - Solicitare moderata din cauza coroziunii
Conformitatea LABS	VDMA24364-B2-L
Nota privind materialele	Conform RoHS
Material carcasa	Aliaj de aluminiu forjat
Interfata Fieldbus	Sub-D, 9 pini, priza
Conector electric	5 pini 7/8" conector rotund