


Portal liniar DHSL-0.5-DGC12-DGSL8

Cod: 574497

FESTO

Pentru a obtine o oferta, va rugam apasati simbolul cerere FAX.

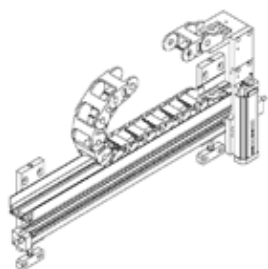

Fisa tehnica

Caracteristica	valoare
Asamblare	Portal 0.5
Incarcatura efectiva	0 ... 0,5 kg
Unitate de actionare, axa Z	DGSL-8
Sistem de actionare, axa Z	pneumatic
Cursa, axa Z	0 ... 100 mm
Acuratete de repetare in pozitia de capat, axa Z	$\pm 0,01$ mm
Unitate de actionare, axa Y	DGC-12
Sistem de actionare, axa Y	pneumatic
Pozitie intermediara, axa Y	x 1
Cursa, axa Y	0 ... 1.900 mm
Acuratete de repetare in pozitia de capat, axa Y	$\pm 0,02$ mm