


Portal liniar DHSL-15-DGC40FAS-EGC80BS

Cod: 574532

FESTO

Pentru a obtine o oferta, va rugam apasati simbolul cerere FAX.

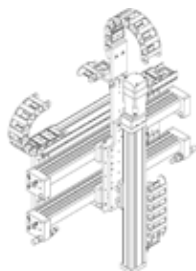

Fisa tehnica

Caracteristica	valoare
Asamblare	Portal 15
Incarcatura efectiva	0 ... 15 kg
Unitate de actionare, axa Z	EGC-80-BS
Sistem de actionare, axa Z	Electric cu arbore melcat
Pozitie intermediara, axa Z	orice
Cursa, axa Z	0 ... 1.000 mm
Acuratete de repetare in pozitia de capat, axa Z	$\pm 0,02$ mm
Acuratete de repetare in pozitia intermediara, axa Z	$\pm 0,02$ mm
Unitate de actionare, axa Y	DGC-40-FA
Sistem de actionare, axa Y	pneumatic
Pozitie intermediara, axa Y	x 1
Cursa, axa Y	0 ... 8.500 mm
Acuratete de repetare in pozitia de capat, axa Y	$\pm 0,02$ mm
Acuratete de repetare in pozitia intermediara, axa Y	$\pm 0,02$ mm