 



# Placa de exhaustare verticala VABF-L1-P7A13-G18

Cod: 574595

FESTO

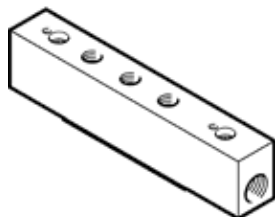

## Fisa tehnica

Caracteristica	valoare
Marimea ramei	16 mm
Numarul maxim de pozitii de ventile	1
Presiune de operare Mpa	-0,09 ... 1 MPa
presiune de operare	-0,9 ... 10 bar
Aprobare	RCM Mark c UL us - Recognized (OL)
Clasa de rezistenta la coroziune KBK	2 - Rezistenta moderata la coroziune
Conformitatea PWIS	VDMA24364-B1/B2-L
Cuplu de strangere maxim la fixarea ventilului	0,65 Nm
Greutate produs	350 g
Conexiune pneumatica 3	G1/8
Conexiune pneumatica 5	G1/8
Indicatie material	conform RoHS
Materialul placii	Aliaj de aluminiu forjat