


## Racord X NPFC-X-R14-3G14-MFFF

Numar piesa: 8030265

FESTO

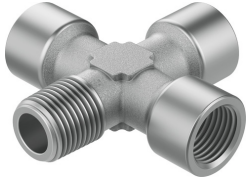

### Fisa de date

Caracteristica	Valoare
Material racord filetat	Alama, nichelata
Unitate de ambalare	10
Presiune de lucru	-0.95 bar...50 bar
Mediu de operare	Aer comprimat conform ISO 8573-1:2010 [-::-:-]
Clasa de rezistenta la coroziune KBK	1 - stres redus la coroziune
Conformitatea LABS	VDMA24364-B1/B2-L
Temperatura ambianta	-20 °C...150 °C
Greutate produs	59.6 g
Conector pneumatic 1	R1/4
Conexiune pneumatica 2	G1/4
Nota privind materialele	Conform RoHS