


Set axial EAMM-A-N80-70GA

Numar piesa: 8063608

FESTO

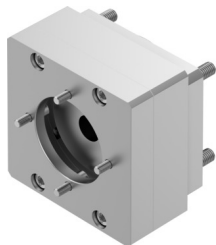

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	48 Nm
Greutate produs	1377 g
Cod de interfata actuator	N80
Codul interfetei motor In	70GA
Nota privind materialele	Conform RoHS