


Kit axial EAMM-A-N80-120GB

Cod: 8063618

FESTO

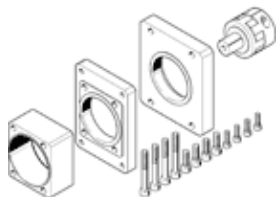

Fisa tehnica

Caracteristica	valoare
pozitie instalare	Oricare
Conformitatea PWIS	VDMA24364-B2-L
Temperatura de depozitare	-25 ... 60 °C
Umiditatea relativa a aerului	0 - 95 %
Tip de protectie	IP40
Temperatura mediului	-10 ... 60 °C
Moment de rotatie transferabil	47 Nm
Greutate produs	2.181 g
Cod interfata actuator	N80
Cod interfata, intrare motor	120GB
Indicatie material	conform RoHS