


Kit adaptare EHAM-E20-40-E9-20

Numar piesa: 8081016

FESTO

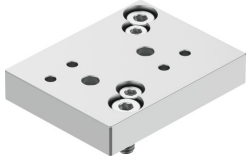

Fisa de date

| Caracteristica | Valoare |
|--------------------------------------|------------------------------|
| Dimensiune | 40 |
| Pozitie de instalare | orice |
| Clasa de rezistenta la coroziune KBK | 1 - stres redus la coroziune |
| Conformitatea LABS | VDMA24364 zona III |
| Temperatura ambianta | -10 °C...70 °C |
| Greutate produs | 36 g |
| Baza de codificare a interfetei | E20 |
| Cod interfata structura | E9 |
| Nota privind materialele | Conform RoHS |
| Material placa de adaptare | Aliaj de aluminiu forjat |