


## Set axial EAMM-A-P4-28B-38AA

Numar piesa: 8107704

FESTO

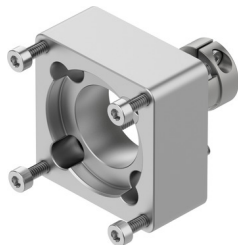

### Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP40
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	0.7 Nm
Greutate produs	59 g
Cod de interfata actuator	P4-28B
Codul interfetei motor In	38AA
Nota privind materialele	Conform RoHS