


# Kit axial EAMM-A-S62-82AA

Cod: 8110211

FESTO

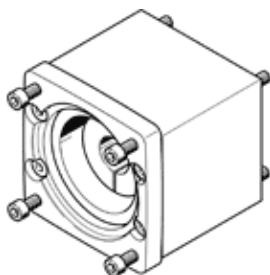

## Fisa tehnica

Caracteristica	valoare
pozitie instalare	Oricare
Conformitatea PWIS	VDMA24364-B2-L
Temperatura de depozitare	-25 ... 60 °C
Umiditatea relativa a aerului	0 - 95 %
Tip de protectie	IP40
Temperatura mediului	-10 ... 60 °C
Moment de rotatie transferabil	21 Nm
Greutate produs	1.050 g
Cod interfata actuator	S62
Cod interfata, intrare motor	82AA
Indicatie material	conform RoHS