


Portal liniar YXCL-2-B

Numar piesa: 8122265

FESTO

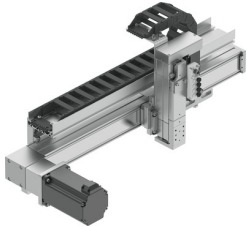

Fisa de date

Caracteristica	Valoare
Planeitatea necesara a suprafetelor de cultivare	0.1 MMM
Pozitie de instalare	orizontala
Structura constructiva	Sistem de portal liniar cu module de actionare electrica si pneumatica
Ciclu de lucru	100%
Conformitatea LABS	VDMA24364 zona III
Temperatura de depozitare	-20 °C...60 °C
Umiditate relativa	0 - 90 %
Tip de protectie	IP40
Temperatura ambianta	5 °C...45 °C
Interval de intretinere	2500 km
Nota privind materialele	Conform RoHS
Material placa de adaptare	Aluminiu, anodizat
Material echer de fixare	Aluminiu Otel inoxidabil aliaj inalt
Material lanturi energetice	Ranforsat cu PA