


# Reductor EMGA-40-A-G12-40P

Cod: 8141733

FESTO

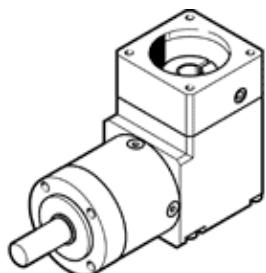

## Fisa tehnica

Caracteristica	valoare
Transmisie flansa	40 mm
Motor cu flansa	40 mm
Joc de rasucire	0,41 deg
tipul reductorului	Reductor in unghi drept
Raport de transmisie	12:1
Viteza maxima de intrare	18.000 1/min
Temperatura de operare reductor	-25 ... 90 °C
Conformitatea PWIS	VDMA24364-B2-L
Tip de protectie	IP54
Cuplu de actionare continua	20 Nm
Momentul de inertie al angrenajului	0,048 kgcm <sup>2</sup>
Cuplu maxim iesire	32 Nm
Eficienta maxima	94 %
rigiditate la torsiune	0,8 Nm/arcmin
Greutate produs	600 g
Interfata reductor arbore de iesire	40G
Interfata reductor arbore de antrenare	40P
Indicatie material	conform RoHS