


# Bobina VACC-S13-18-K4-1UF-KS4ME

Cod: 8156762

FESTO

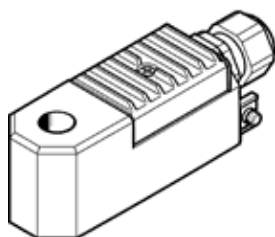

## Fisa tehnica

Caracteristica	valoare
tip de actionare	electric
pozitie instalare	Oricare
Afisarea pozitiei de comutare	nu
Protectie interna	Siguranta de protectie
Durata de anclansare	100 %
Clasa izolatie	H
Caracteristica bobina	24 V DC: 1.8 W 24 V AC: 40/65 Hz, putere 1.8 VA
Oscilatii admisibile ale tensiunii	-15 % / +10 %
Certificat ATEX in afara UE	EPL Db (KR) EPL Gb (KR)
Departament eliberare certificate	21-AV4BO-0279X 22-AV4BO-0051X
Tip gaz cu protectie la explozie si aprindere	Ex e mb IIC T4, T5, T6
Tip praf cu protectie la aprindere si explozie	Ex tD A21 IP65 T85/T95/T130°C
Protectie la explozie temperatura ambientala	T4,T130°C: -30°C ≤ Ta ≤ +60°C T5,T95°C: -30°C ≤ Ta ≤ +60°C T6,T85°C: -30°C ≤ Ta ≤ +50°C
Conformitatea PWIS	VDMA24364-zona III
Tip de protectie	IP65
Greutate produs	330 g
Conectare electrica	Cutie terminal, cablu filetat M20x1.5
Indicatie material	conform RoHS