


Set axial EAMM-A-D100-150A-S1

Numar piesa: 8157276

FESTO

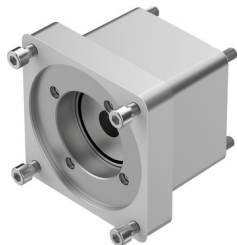

Fisa de date

Caracteristica	Valoare
Pozitie de instalare	orice
Conformitatea LABS	VDMA24364-B2-L
Temperatura de depozitare	-25 °C...60 °C
Umiditate relativa	0 - 95 %
Tip de protectie	IP65
Temperatura ambianta	-10 °C...60 °C
Cuplu transmisibil	143 Nm
Greutate produs	3444 g
Cod de interfata actuator	D100B
Codul interfetei motor In	140A 150A
Nota privind materialele	Conform RoHS