


Kit axial EAMM-A-K95-150A

Cod: 8157278

FESTO

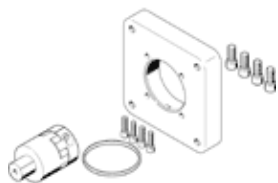

Fisa tehnica

Caracteristica	valoare
pozitie instalare	Oricare
Conformitatea PWIS	VDMA24364-B2-L
Temperatura de depozitare	-25 ... 60 °C
Umiditatea relativa a aerului	0 - 95 %
Tip de protectie	IP40
Temperatura mediului	-10 ... 60 °C
Moment de rotatie transferabil	143 Nm
Greutate produs	1.986 g
Cod interfata actuator	K95
Cod interfata, intrare motor	140A 150A
Indicatie material	conform RoHS