 



# Utikač NECU-S-M8G4-C2

Broj artikla: 1068198

FESTO

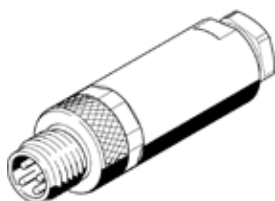

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	EN 61076-2-104
Frekvencija priključivanja	100
Cable outlet	Ravno
Težina proizvoda	9,1 g
Electrical connection 1, design	okruglo
Electrical connection 1, connection type	Utikači
Electrical connection 1, connection technology	M8x1, A-coded to EN 61076-2-104
Electrical connection 1, number of pins/wires	4
Electrical connection 1, type of mounting	Screw lock with A/F9
Electrical connection 2, connection technology	Vijčana stezaljka
Područje pogonskog napona DC	0 ... 30 V
Područje pogonskog napona AC	0 ... 30 V
Strujna opteretivost kod 40°C	4 A
Čvrstoća na udarno naprezanje	0,8 kV
Prečnik kabela	3,5 ... 5 mm
Nazivni presek provodnika	0,14 ... 0,5 mm <sup>2</sup>
Mehanička zaštita	IP67
Note on degree of protection	u montiranom stanju
Temperatura okoline	-25 ... 85 °C
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Klasa korozione otpornosti KBK	1 - Low corrosion stress
Material housing	PA
Boja kućišta	crno
Material screw-type lock	Nickel-plated brass
Material electrical contact	Brass, gold-plated