

 

# Prigušivač zvuka AMTE-M-LH-G18

Broj artikla: 1205860

★ Kernprogramm

FESTO

Suitable for reducing noise at the exhaust ports of pneumatic systems.

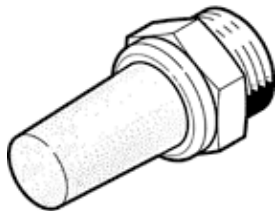

## Tehnički podaci

Svojstvo	Vrednost
Položaj ugradnje	proizvoljno
Veličina kontejnera	20
Operating pressure MPa	0 ... 1 MPa
Pogonski pritisak	0 ... 10 bar
Protok prema atmosferi	1.735 l/min
Pogonski medijum	Kompresovani vazduh prema ISO 8573-1:2010 [7:-:-]
Napomena o mediju pogona i upravljanja	Moguć nauljeni pogon
Klasa korozione otpornosti KBK	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Nivo zvučnog pritiska	76 dB(A)
Temperatura okoline	-40 ... 80 °C
Težina proizvoda	7,5 g
Pneumatski priključak	G1/8
Material of silencer insert	Bronza
Material of threaded plug	Mesing
Materijal - napomena	RoHS komfornost