 



Prigušivač zvuka U-3/8-B-NPT

Broj artikla: 12740

FESTO

For reducing noise and avoiding contamination at the exhaust ports of pneumatic components.

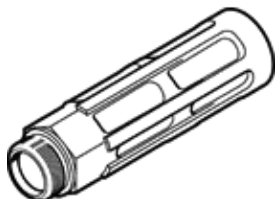

Tehnički podaci

Svojstvo	Vrednost
Položaj ugradnje	proizvoljno
Operating pressure for entire temperature range	0 ... 1 MPa
Pogonski pritisak kompletnog temperaturnog područja	0 ... 10 bar
Operating pressure for entire temperature range	0 ... 145 psi
Protok prema atmosferi	4.500 l/min
Pogonski medijum	Kompresovani vazduh prema ISO 8573-1:2010 [7:-:-]
Napomena o mediju pogona i upravljanja	Moguć nauljeni pogon
Klasa korozione otpornosti KBK	1 - Low corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
Nivo zvučnog pritiska	80 dB(A)
Temperatura okoline	-10 ... 70 °C
Težina proizvoda	37 g
Pneumatski priključak	3/8 NPT
Material of silencer insert	PE
Material of threaded plug	Aluminijum
Materijal - napomena	RoHS komfornost
Material housing	Aluminijum