

Motorski vod


NEBM-S1W15-E-7-Q7-LE6

Broj artikla: 1450946

★ Kernprogramm

odgovara za koračni motor EMMS-ST...

FESTO

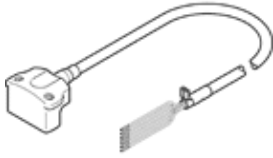

Tehnički podaci

| Svojstvo | Vrednost |
|--|--------------------------------------|
| Cable identification | Without inscription label holder |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | ugaono |
| Electrical connection 1, connection type | Utičnica |
| Electrical connection 1, cable outlet | Angled |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 15 |
| Electrical connection 1, occupied pins/wires | 10 |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | Kabl |
| Electrical connection 2, connection technology | otvoreni kraj |
| Electrical connection 2, number of pins/wires | 6 |
| Electrical connection 2, occupied pins/wires | 6 |
| Područje pogonskog napona DC | 0 ... 72 V |
| Nazivni pogonski napon DC | 24 V |
| Dužina kabela | 7 m |
| Svojstvo kabela | Suitable for energy chains |
| Bending radius, flexible cable installation | ≥ 80 mm |
| Prečnik kabela | 8 mm |
| Struktura kabela | 6x0,75 zaslonjeno |
| Nazivni presek provodnika | 0,75 mm ² |
| Krajevi žica | Završetak žice |
| Mehanička zaštita | IP65 |
| Note on degree of protection | u montiranom stanju |
| Temperatura okoline | -40 ... 80 °C |
| Temperatura okoline kod pokretnog postepenja kablova | -5 ... 80 °C |
| CE znak (vidi izjavu o usklađenosti) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Materijal - napomena | RoHS komfornost |
| Klasa korozione otpornosti KBK | 0 - No corrosion stress |
| Material cable sheath | TPE-U(PUR) |
| Boja izolacije | sivo |