


# Ugaona utičnica PEV-1/4-WD-LED-24

Broj artikla: 164274

FESTO

za pritiski prekidač, sa LED-om.

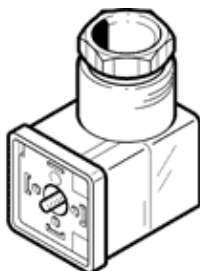

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	EN 175301-803
Indikacija stanja	LED žuti LED zeleni
Vrsta pričvršćenja	vijčano pričvršćen
Cable outlet	Angled
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, connection technology	Plug pattern type A based on EN 175301-803
Electrical connection 1, number of pins/wires	4
Electrical connection 1, occupied pins/wires	4
Electrical connection 1, type of mounting	Central screw M3
Electrical connection 2, function	Controller side
Electrical connection 2, connection technology	Vijčana stezaljka
Electrical connection 2, number of pins/wires	5
Electrical connection 2, occupied pins/wires	5
Područje pogonskog napona DC	15 ... 30 V
Strujna opteretivost kod 40°C	8 A
Navojni spoj kabla	Pg11
Dozvoljeni prečnik kabla	4,5 ... 11 mm
Presek priključka	0,25 ... 1,5 mm <sup>2</sup>
Mehanička zaštita	IP65
Note on degree of protection	u montiranom stanju
Temperatura okoline	-40 ... 80 °C
Note on ambient temperature	Note derating
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Material housing	PA6 - ojačano
Boja kućišta	transparentno
Material electrical contact	Mesing Niklovano pocinkovano