

 

Priključni kabl

KMPYE-AIF-1-GS-GD-2

Broj artikla: 170238

FESTO

predugrađeno, za proporcionalni razvodnik.

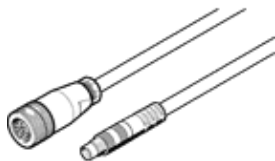

Tehnički podaci

| Svojstvo | Vrednost |
|--|---|
| Odgovara standardu | EN 61076-2-101 |
| Dodatne funkcije | Product-specific pin allocation |
| Cable identification | sa priborom |
| Frekvencija priključivanja | 500 |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | okruglo |
| Electrical connection 1, connection type | Utičnica |
| Electrical connection 1, cable outlet | Ravno |
| Electrical connection 1, connection technology | M12x1, A-coded in accordance with EN 61076-2-101 |
| Electrical connection 1, number of pins/wires | 4 |
| Electrical connection 1, occupied pins/wires | 4 |
| Electrical connection 1, type of mounting | Screw-type lock with width across flats 18 and longitudinal knurl |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, design | okruglo |
| Electrical connection 2, connection type | Utikači |
| Electrical connection 2, cable outlet | Ravno |
| Electrical connection 2, connection technology | M9x0,5 |
| Electrical connection 2, number of pins/wires | 7 |
| Electrical connection 2, occupied pins/wires | 6 |
| Electrical connection 2, type of mounting | Screw lock |
| Područje pogonskog napona DC | 0 ... 50 V |
| Strujna opteretivost kod 40°C | 1 A |
| Čvrstoća na udarno naprezanje | 2 kV |
| Dužina kabela | 2 m |
| Svojstvo kabela | Suitable for energy chains |
| Uslovi ispitivanja kabela | Uslovi ispitivanja na zahtev |
| Bending radius, flexible cable installation | ≥ 75 mm |
| Prečnik kabela | 5,6 mm |
| Struktura kabela | 8x0,24 zaslonjeno |
| Nazivni presek provodnika | 0,24 mm ² |
| Mehanička zaštita | IP65 |
| Note on degree of protection | u montiranom stanju |
| Temperatura okoline | -25 ... 85 °C |
| Temperatura okoline kod pokretnog postepenja kablova | -5 ... 80 °C |
| PWIS conformity | VDMA24364-B2-L |
| Materijal - napomena | RoHS komformnost |
| Stepen zagađenja | 1 |
| Material cable sheath | TPE-U(PUR) |
| Boja izolacije | crno |