 



Spojni vod KMPV-SUB-D-15-10

Broj artikla: 177674

FESTO

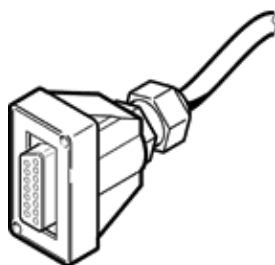

Tehnički podaci

Svojstvo	Vrednost
Zasnovano na normi	DIN 41652
Cable identification	sa priborom
Frekvencija priključivanja	50
Težina proizvoda	400 g
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utičnica
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	15
Electrical connection 1, occupied pins/wires	15
Electrical connection 1, type of mounting	2x M3 screws
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	15
Electrical connection 2, occupied pins/wires	15
Područje pogonskog napona DC	≤ 30 V
Nazivni pogonski napon DC	24 V
Dozvoljeno strujno opterećenje	2,8 A
Čvrstoća na udarno naprezanje	1 kV
Dužina kabla	10 m
Svojstvo kabla	Standard
Uslovi ispitivanja kabla	Uslovi ispitivanja na zahtev
Bending radius, fixed cable installation	≥ 82 mm
Prečnik kabla	8,2 mm
Odstupanje prečnika kabla	± 0,2 mm
Struktura kabla	15x0,25
Nazivni presek provodnika	0,25 mm ²
Krajevi žica	Cut off bluntly
Mehanička zaštita	IP65
Note on degree of protection	u montiranom stanju
Temperatura okoline	-20 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Material cable sheath	TPE-U(PUR)
Boja izolacije	sivo
Material housing	PA
Boja kućišta	crno
Material seals	CR
Material electrical contact	Bakarna legura pozlačeno