

# Vod upravljanja

 

## NEBC-S1H15-E-5.0-N-LE15

Broj artikla: 2052918

Komponenta koja će prestati da se proizvodi

Komponenta se više ne proizvodi. Isporučuje se do 2023. Vidi Support Portal za alternativni proizvod.

FESTO

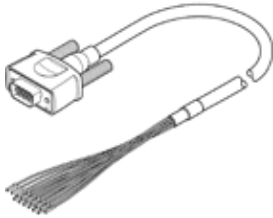

## Tehnički podaci

Svojstvo	Vrednost
Odgovara standardu	DIN 47100
Cable identification	Without inscription label holder
Electrical connection 1, function	Field device side
Electrical connection 1, design	ugaono
Electrical connection 1, connection type	Utikači
Electrical connection 1, cable outlet	Ravno
Electrical connection 1, connection technology	Sub-D
Electrical connection 1, number of pins/wires	15
Electrical connection 1, occupied pins/wires	15
Electrical connection 1, type of mounting	2x screw 4-40 UNC-2A
Electrical connection 2, function	Controller side
Electrical connection 2, connection type	Kabl
Electrical connection 2, connection technology	otvoreni kraj
Electrical connection 2, number of pins/wires	15
Electrical connection 2, occupied pins/wires	15
Područje pogonskog napona DC	0 ... 30 V
Nazivni pogonski napon DC	24 V
Dužina kabla	5 m
Svojstvo kabla	prikladno za energetske lanac
Bending radius, fixed cable installation	≥ 33 mm
Prečnik kabla	6,6 mm
Struktura kabla	18x0,14
Nazivni presek provodnika	0,14 mm <sup>2</sup>
Krajevi žica	Završetak žice
Mehanička zaštita	IP50
Note on degree of protection	u montiranom stanju
Temperatura okoline	-30 ... 80 °C
Temperatura okoline kod pokretnog postepenja kablova	-30 ... 80 °C
CE znak (vidi izjavu o usklađenosti)	in accordance with EU RoHS directive
UKCA marking (see declaration of conformity)	To UK RoHS instructions
PWIS conformity	VDMA24364-B2-L
Materijal - napomena	RoHS komfornost
Stepen zagađenja	3
Material cable sheath	TPE-U(PUR)
Boja izolacije	sivo