


Adaptive Gripper Finger DHAS-GF-80-U-BU

Broj artikla: 3998964

FESTO

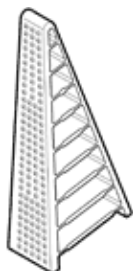

Tehnički podaci

Svojstvo	Vrednost
Veličina	80
Položaj ugradnje	proizvoljno
Klasa korozione otpornosti KBK	2 - Moderate corrosion stress
PWIS conformity	VDMA24364-B1/B2-L
RSBP classification to CD-0033	F1a
Food-safe	See Supplementary material information
Temperatura okoline	10 ... 50 °C
Težina proizvoda	13 g
Materijal - napomena	RoHS komfornost
Material clamp jaws	TPE-U(PU)