

Priključni kabl

KMP6-25P-20-10


Broj artikla: 530048

Classic - nicht für Neukonstruktionen verwenden

za ventilski blok CPA-SC, sa Sub-D utikačem 25-polnim za

Modern alternatives can be found by entering the first four characters of the type code in the search field.

FESTO

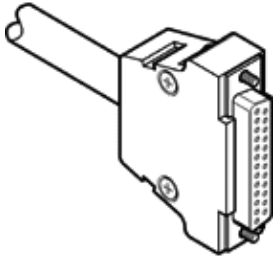

Tehnički podaci

| Svojstvo | Vrednost |
|--|--|
| Odgovara standardu | DIN 41652 |
| Cable identification | Without inscription label holder |
| Frekvencija priključivanja | 50 |
| Težina proizvoda | 1.600 g |
| Electrical connection 1, function | Field device side |
| Electrical connection 1, design | ugaono |
| Electrical connection 1, connection type | Utičnica |
| Electrical connection 1, cable outlet | Ravno |
| Electrical connection 1, connection technology | Sub-D |
| Electrical connection 1, number of pins/wires | 25 |
| Electrical connection 1, occupied pins/wires | 25 |
| Electrical connection 1, type of mounting | 2 screws 4-40 UNC |
| Electrical connection 2, function | Controller side |
| Electrical connection 2, connection type | Kabl |
| Electrical connection 2, connection technology | otvoreni kraj |
| Electrical connection 2, number of pins/wires | 25 |
| Electrical connection 2, occupied pins/wires | 25 |
| Područje pogonskog napona DC | 0 ... 30 V |
| Nazivni pogonski napon DC | 24 V |
| Strujna opteretivost kod 40°C | 2,8 A |
| Čvrstoća na udarno naprezanje | 1 kV |
| Dužina kabla | 10 m |
| Svojstvo kabla | Standard |
| Uslovi ispitivanja kabla | Uslovi ispitivanja na zahtev |
| Bending radius, fixed cable installation | ≥ 103 mm |
| Bending radius, flexible cable installation | ≥ 103 mm |
| Prečnik kabla | 10,3 mm |
| Odstupanje prečnika kabla | ± 0,25 mm |
| Struktura kabla | 20x0,25+5x0,34 |
| Nazivni presek provodnika | 0,25 mm ² 0,34 mm ² |
| Krajevi žica | Cut off bluntly |
| Mehanička zaštita | IP40 |
| Note on degree of protection | u montiranom stanju |
| Temperatura okoline | -25 ... 70 °C |
| Temperatura okoline kod pokretnog postepenja kablova | -5 ... 70 °C |
| Temperatura ležaja | -25 ... 75 °C |
| CE znak (vidi izjavu o usklađenosti) | in accordance with EU RoHS directive |
| UKCA marking (see declaration of conformity) | To UK RoHS instructions |
| PWIS conformity | VDMA24364-B2-L |
| Materijal - napomena | RoHS komformnost |
| Stepen zagađenja | 2 |

| Svojstvo | Vrednost |
|-----------------------------|--------------------------|
| Material cable sheath | PVC |
| Boja izolacije | sivo |
| Material housing | PBT ojačan |
| Boja kućišta | sivo |
| Material screw-type lock | Nickel-plated brass |
| Material electrical contact | Gold-plated copper alloy |